

Ball thrust bearings :


Determination of the a_{ISO} coefficient

5 a_{ISO}


Favorable operating conditions

Uncertain operating conditions

Unfavourable operating conditions

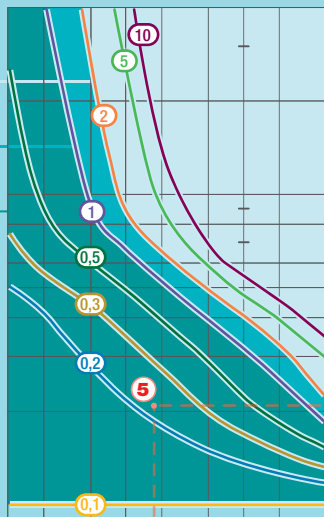


4 Real cinematic viscosity (cSt)

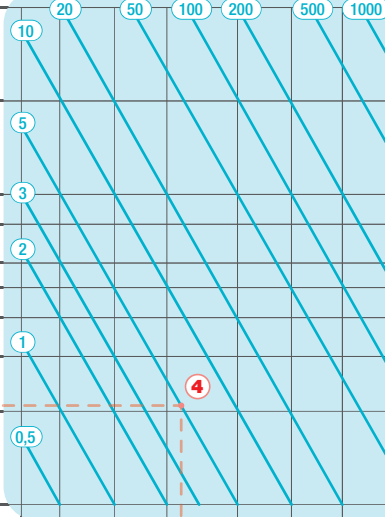

2 Dm (mm)




3 Rotation speed (tr/min)

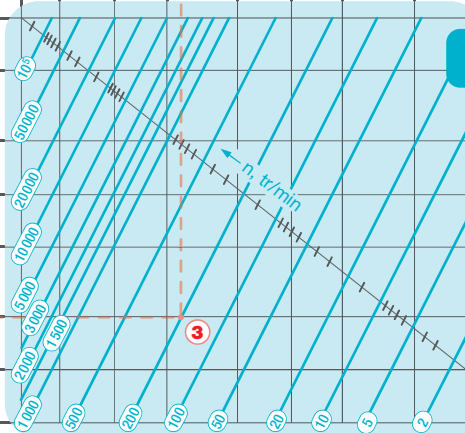

1 Load and contamination (Co/P)

- High cleanliness
- Normal cleanliness
- Light contamination
- High contamination

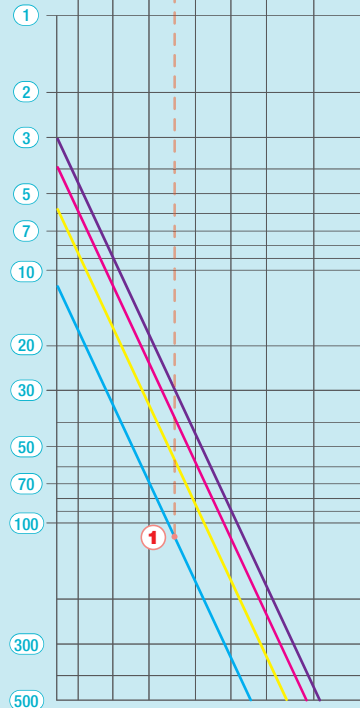

Spherical roller thrust bearings :


Determination of the a_{ISO} coefficient

5 a_{ISO}


Favorable operating conditions

Uncertain operating conditions


Unfavourable operating conditions

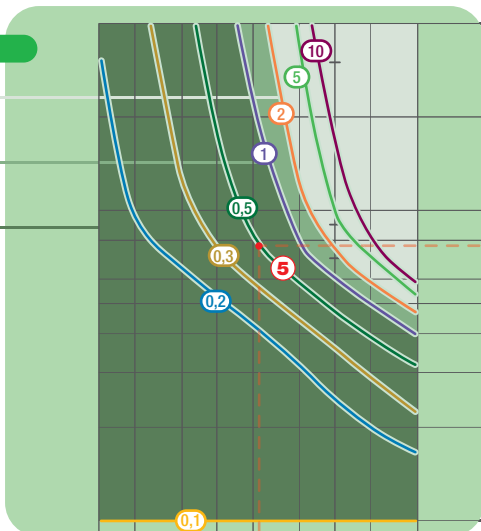


4 Real cinematic viscosity (cSt)

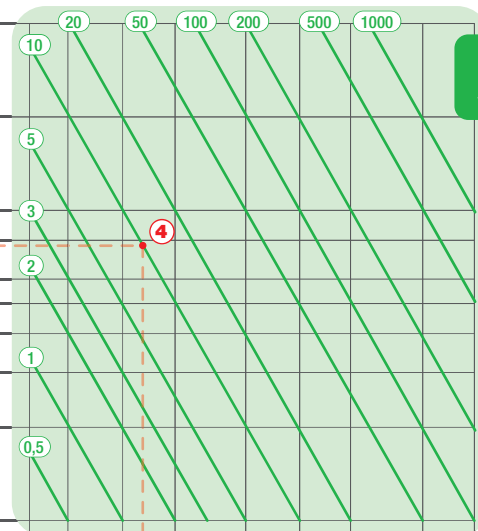

2 Dm (mm)

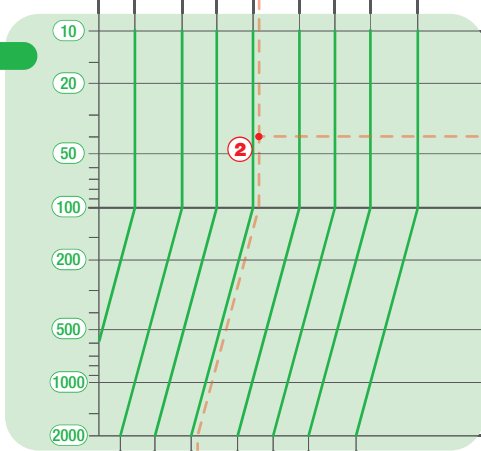

3 Rotation speed (tr/min)

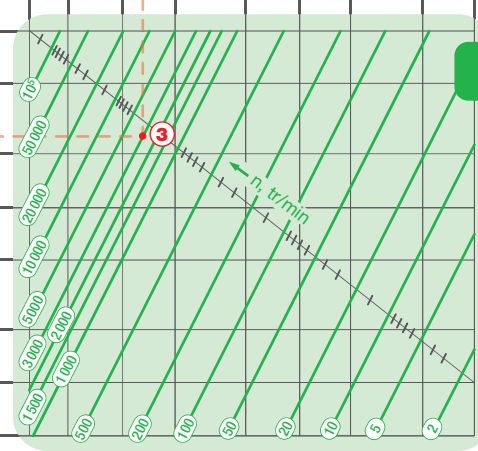

1 Load and contamination (Co/P)

- High cleanliness
- Normal cleanliness
- Light contamination
- High contamination

